



ISOMETRIC VIEW

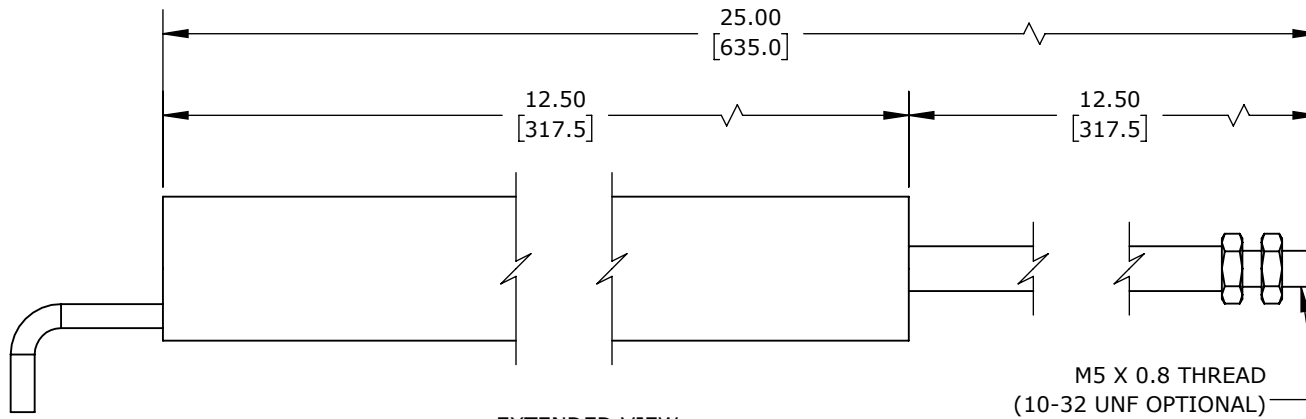

EXTENDED VIEW

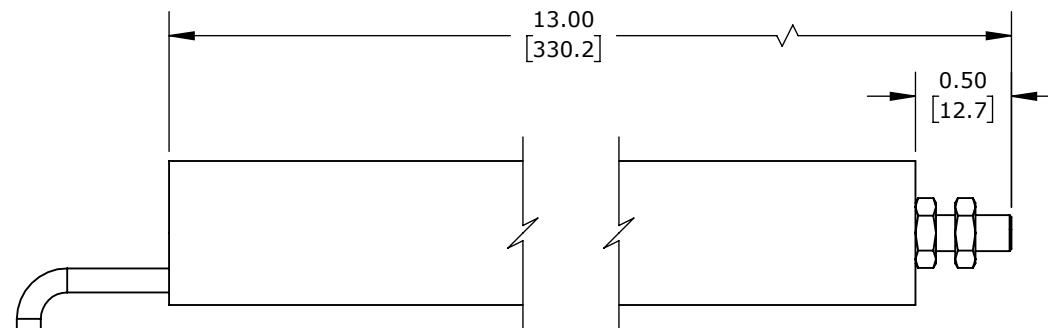

RETRACTED VIEW

Ø0.75  
[19.1] JAM NUT

4-CONDUCTOR SHIELDED CABLE,  
1 METER LONG

ALLIANCE SENSORS INDUCTIVE LINEAR POSITION SENSOR, SLIDE, 300MM STROKE, 5.2MM SHAFT DIAMETER, 0-10 VDC OUTPUT, 19MM DIAMETER X 317.5MM BODY, M5 X 0.8 MOUNT, PIGTAIL, 3.2FT/1M CABLE LENGTH.

**LZE19-300A-00-10S**

AutomationDirect.com  
1-800-633-0405



3rd  
ANGLE

NOT TO  
SCALE

PART DIMENSIONS MAY DIFFER SLIGHTLY  
DUE TO MANUFACTURER'S VARIANCES

METRIC UNITS USED  
FOR PART DESIGN

UNLESS OTHERWISE  
SPECIFIED UNITS ARE:

**inch**  
**[mm]**

LATEST VERSION  
3/22/2022

SHEET 1 OF 1