








Automation Direct Part#	Rated Voltage	Amps	Phase	Weight (LBS)
VTF-246-LPQ	600	35	3	17
VTF-246-MQR	600	45	3	17
VTF-246-NRS	600	55	3	17

See VTF Installation Guide For  
Terminal Wire Size And Torque Information.

Note: Maintain Clearance of 3 Inches To Other Equipment.

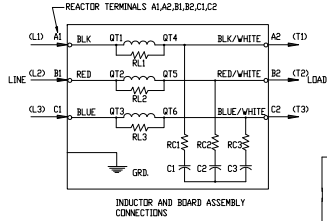

 (Customer Connections)  
Markings On Terminal Block  
For Reference Only.

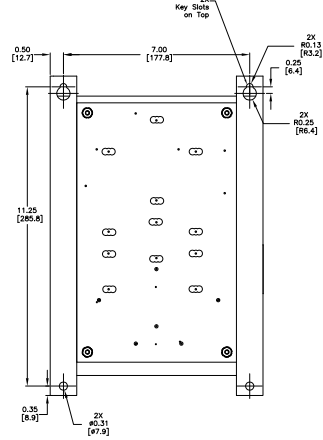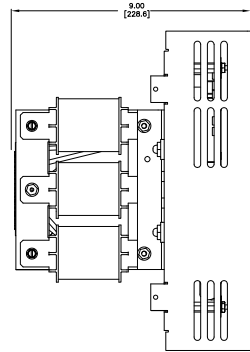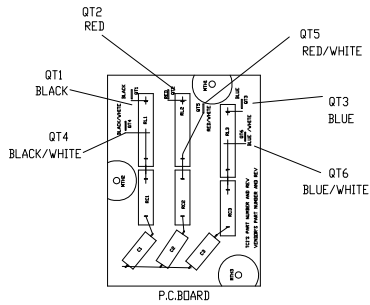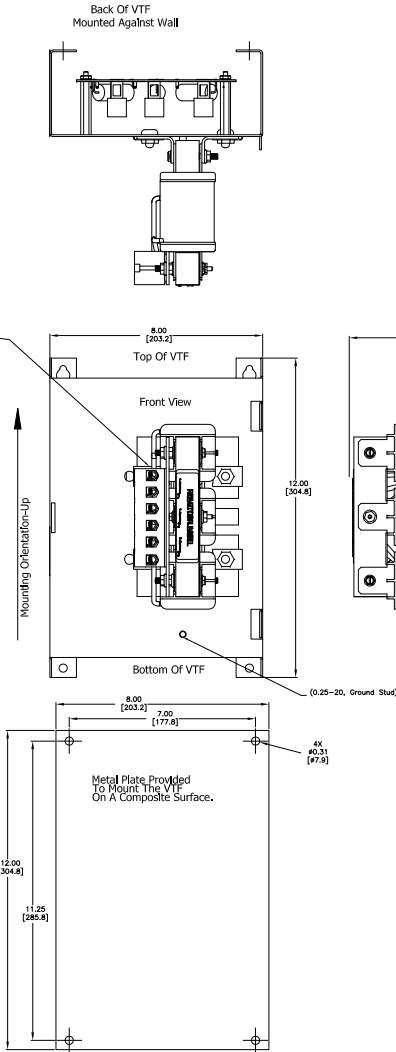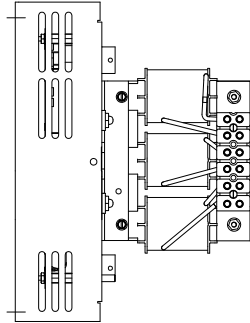

#### NOTES:

1. DIMENSIONS CAN BE CHANGED BY MANUFACTURER WITHOUT NOTICE.
2. DIMENSIONS DO NOT IMPLY TOLERANCE.

#### VTF-246-NRS

Units: inches [mm]

Scale: Full

**VTF SERIES OUTPUT FILTER,  
230/460/575 VAC, 20HP, 40HP, 50HP,  
3-PHASE, 55A, OUTPUT SIDE ONLY**

**AUTOMATIONDIRECT**.com