

Dimensions:
mm
[inches]

POLYCARBONATE
VERSION ONLY



UL US LISTED
FILE #E65324
TYPE 4,4X,6,6P


Enclosures can be Factory Modified (Milling, Drilling, Printing etc.)
Contact Factory (modshop@hammfg.com) for quotes
Solid models of this enclosure available in .stp or .x_t.
(Part number and text placement/orientation on our products are subject to change,
we do not recommend using them as a locating reference for modification purposes)

NOTE

Purchased assembly includes box, lid, 4 cover screws, preformed silicone gasket, 4 rubber feet, 4 wall mount foot screws, and 4 wall mount feet.
General Purpose ABS version is not UL approved. (Matl UL94 - HB)
Polycarbonate version is UL 508A approved. (Matl UL94 - 5VA @ 3mm)

Recommended Cover Screw Torque - 71-85 ozf-in (50-60 cN-m)

| | | |
|-------------------------|--|--|
| 1557 | | |
| 1557FA Enclosure | | |
| | General Purpose ABS Black Enclosure | 1557FABK |
| | General Purpose ABS Grey Enclosure | 1557FAGY |
| | Polycarbonate Black Enclosure | 1557FA2BK |
| | Polycarbonate Grey Enclosure | 1557FA2GY |
| ACCESSORIES | | |
| | Silicone Pre-formed Gasket Black (Pkg 2) | 1557FGASKET |
| | Clear Rubber Feet (Pkg 24) | 1421T6CL |
| 5 1 | Stainless Steel Cover Screws [M4-0.7 X 20mm] (Pkg 50) | SC576-50 |
| | Steel P.C.Board Screw [#6 X 1/4" Self Tapping] (Pkg 50) | SC526-50 |
| | Stainless Steel Wall Mount foot Screw [#8 X 3/8" Self Tapping] (Pkg 50) | SC556-50 |
| | Wall Mout Foot Kit [wall mount foot] (Pkg 24) [#8 X 3/8" Self Tapping] (Pkg 24) | General Purpose ABS Grey 1557FOOTGY-24 General Purpose ABS Black 1557FOOTBK-24 POLYCARBONATE Grey 1557FOOT2GY-24 POLYCARBONATE Black 1557FOOT2BK-24 |

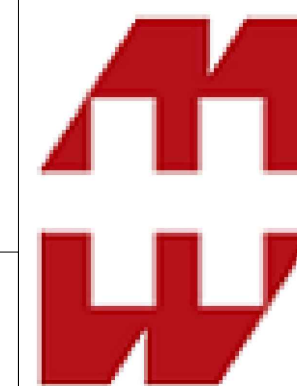

**HAMMOND
MANUFACTURING®**

1557FA

www.hammondmfg.com