

Dimensions:
mm
[inches]

POLYCARBONATE
VERSION ONLY



FILE #E65324
TYPE 4,4X,6,6P


Enclosures can be Factory Modified (Milling, Drilling, Printing etc.)
Contact Factory (modshop@hammfg.com) for quotes
Solid models of this enclosure available in .stp or .x_t.
(Part number and text placement/orientation on our products are subject to change,
we do not recommend using them as a locating reference for modification purposes)

NOTE

Purchased assembly includes box, lid, 4 cover screws, preformed silicone gasket, 4 rubber feet, 4 wall mount foot screws, and 4 wall mount feet.
General Purpose ABS version is not UL approved. (Matl UL94 - HB)
Polycarbonate version is UL 508A approved. (Matl UL94 - 5VA @ 3mm)

Recommended Cover Screw Torque - 71-85 ozf-in (50-60 cN-m)

1557		
1557FA Enclosure		
	General Purpose ABS Black Enclosure	1557FABK
	General Purpose ABS Grey Enclosure	1557FAGY
	Polycarbonate Black Enclosure	1557FA2BK
	Polycarbonate Grey Enclosure	1557FA2GY
ACCESSORIES		
	Silicone Pre-formed Gasket Black (Pkg 2)	1557FGASKET
	Clear Rubber Feet (Pkg 24)	1421T6CL
5 1	Stainless Steel Cover Screws [M4-0.7 X 20mm] (Pkg 50)	SC576-50
	Steel P.C.Board Screw [#6 X 1/4" Self Tapping] (Pkg 50)	SC526-50
	Stainless Steel Wall Mount foot Screw [#8 X 3/8" Self Tapping] (Pkg 50)	SC556-50
	Wall Mout Foot Kit [wall mount foot] (Pkg 24) [#8 X 3/8" Self Tapping] (Pkg 24)	General Purpose ABS Grey 1557FOOTGY-24 General Purpose ABS Black 1557FOOTBK-24 POLYCARBONATE Grey 1557FOOT2GY-24 POLYCARBONATE Black 1557FOOT2BK-24

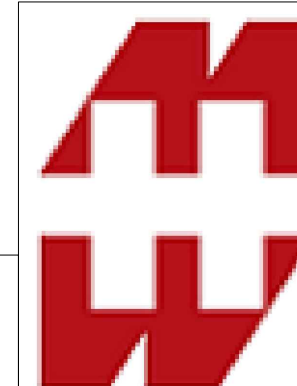

**HAMMOND
MANUFACTURING®**

1557FA

www.hammondmfg.com